


RTD1-S04-04 Cut Sheet

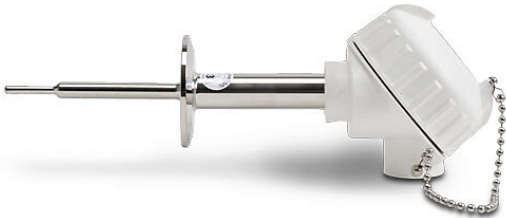

ProSense temperature sensor, Pt100 RTD, sanitary connection probe, 4in insertion length, 3/8in reduced to 3/16in probe diameter, stainless steel sheath, 2in sanitary tri-clamp process connection, white polypropylene screw cover head with terminals.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD1-S04-04>

Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Pt100 RTD
Sensor Type	Sanitary connection probe
Accuracy	Class A accuracy
Insertion Length	4in
Probe Diameter	3/8in reduced to 3/16in
Sheath Material	Stainless steel
Process Connection	2in sanitary tri-clamp
Electrical Connection	White polypropylene screw cover head with terminals
Temperature Sensing Range	-58 to 400 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document
Other	3-A Document