


RTD180-18000 Cut Sheet

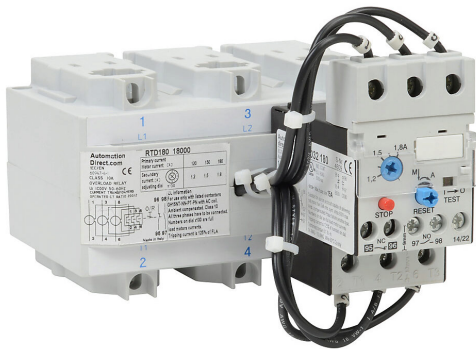

AutomationDirect RTD180 series thermal overload relay, 120.0-180.0A adjustable, bi-metallic, pass through connection(s), panel mount. For use with GH15NT or GH15PT 110mm contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD180-18000>

Technical Specifications

| | |
|--------------------------|-----------------------------------|
| Brand | AutomationDirect |
| Item | Relay |
| Series | RTD180 |
| Relay Type | Thermal overload |
| Full Load Amperage Range | 120.0-180.0A adjustable |
| Operation Type | Bi-metallic |
| Auxiliary Contacts | (1) N.O. / (1) N.C. |
| Trip Class | Trip Class 10 |
| Phase Loss Sensitive | Yes |
| Connection | Pass through |
| Mounting | Panel |
| For Use With | GH15NT or GH15PT 110mm contactors |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | E191059 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/RTD180-18000.pdf>
See store item page for other formats.