


# RTD32-1400 Cut Sheet

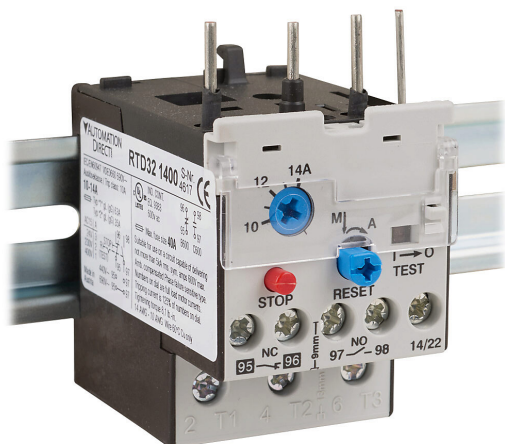

AutomationDirect RTD32 series thermal overload relay, 10.0-14.0A adjustable, bi-metallic, direct mount power connection(s), DIN rail mount. For use with GH15CN to GH15FT 45mm contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD32-1400>

## Technical Specifications

Brand	AutomationDirect
Item	Relay
Series	RTD32
Relay Type	Thermal overload
Full Load Amperage Range	10.0-14.0A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10A
Phase Loss Sensitive	Yes
Connection	Direct mount power
Mounting	DIN rail
For Use With	GH15CN to GH15FT 45mm contactors

## Agency Approvals

UL Listed File #	E191072
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>