


RTD32-1800 Cut Sheet

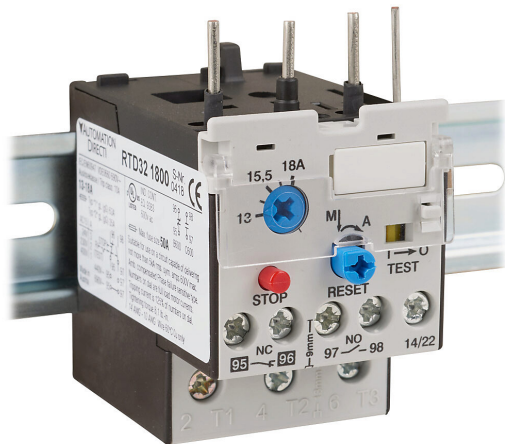

AutomationDirect RTD32 series thermal overload relay, 13.0-18.0A adjustable, bi-metallic, direct mount power connection(s), DIN rail mount. For use with GH15DN, GH15ET, or GH15FT 45mm contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD32-1800>

Technical Specifications

Brand	AutomationDirect
Item	Relay
Series	RTD32
Relay Type	Thermal overload
Full Load Amperage Range	13.0-18.0A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10A
Phase Loss Sensitive	Yes
Connection	Direct mount power
Mounting	DIN rail
For Use With	GH15DN, GH15ET, or GH15FT 45mm contactors

Agency Approvals

UL Listed File #	E191072
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document