


# RTD32-600 Cut Sheet

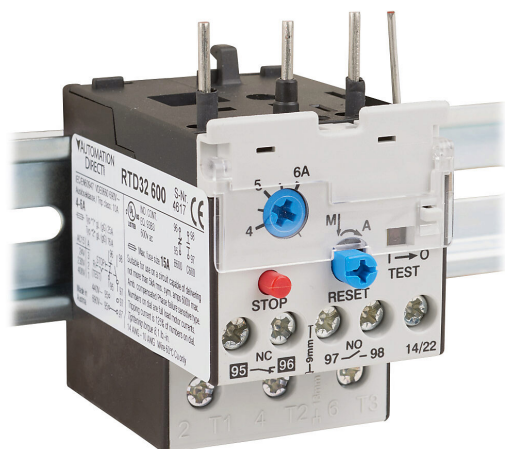

AutomationDirect RTD32 series thermal overload relay, 4.0-6.0A adjustable, bi-metallic, direct mount power connection(s), DIN rail mount. For use with GH15BN to GH15FT 45mm contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD32-600>

## Technical Specifications

<b>Brand</b>	AutomationDirect
<b>Item</b>	Relay
<b>Series</b>	RTD32
<b>Relay Type</b>	Thermal overload
<b>Full Load Amperage Range</b>	4.0-6.0A adjustable
<b>Operation Type</b>	Bi-metallic
<b>Auxiliary Contacts</b>	(1) N.O. / (1) N.C.
<b>Trip Class</b>	Trip Class 10A
<b>Phase Loss Sensitive</b>	Yes
<b>Connection</b>	Direct mount power
<b>Mounting</b>	DIN rail
<b>For Use With</b>	GH15BN to GH15FT 45mm contactors

## Agency Approvals

<b>UL Listed File #</b>	E191072
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>