


RTD32-60 Cut Sheet

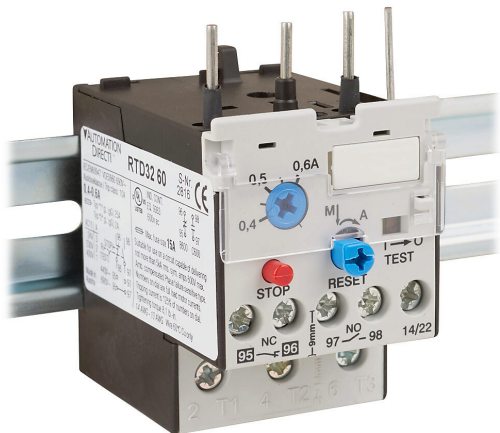

AutomationDirect RTD32 series thermal overload relay, 0.4-0.6A adjustable, bi-metallic, direct mount power connection(s), DIN rail mount. For use with GH15BN to GH15FT 45mm contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD32-60>

Technical Specifications

Brand	AutomationDirect
Item	Relay
Series	RTD32
Relay Type	Thermal overload
Full Load Amperage Range	0.4-0.6A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10A
Phase Loss Sensitive	Yes
Connection	Direct mount power
Mounting	DIN rail
For Use With	GH15BN to GH15FT 45mm contactors

Agency Approvals

UL Listed File #	E191072
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document