


# RW117-3D3-U097 Cut Sheet

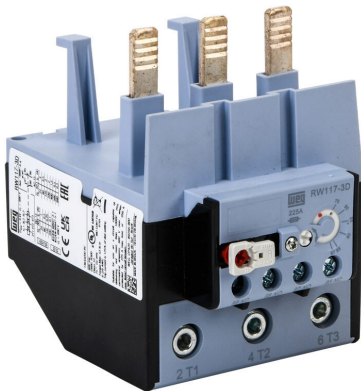

WEG Electric RW117-3D series thermal overload relay, 75.0-97.0A adjustable, bi-metallic, direct mount power connection(s). For use with CWB95 to CWB125 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW117-3D3-U097>

## Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RW117-3D
Relay Type	Thermal overload
Full Load Amperage Range	75.0-97.0A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB95 to CWB125 series contactors

## Agency Approvals

UL Listed File #	E189202
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/RW117-3D3-U097.pdf>  
See store item page for other formats.