


RW117-3D3-U112 Cut Sheet

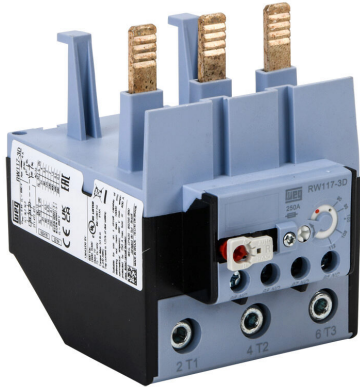

WEG Electric RW117-3D series thermal overload relay, 90.0-112.0A adjustable, bi-metallic, direct mount power connection(s). For use with CWB95 to CWB125 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW117-3D3-U112>

Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RW117-3D
Relay Type	Thermal overload
Full Load Amperage Range	90.0-112.0A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O./ (1) N.C.
Trip Class	Trip Class 10
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB95 to CWB125 series contactors

Agency Approvals

UL Listed File #	E189202
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/RW117-3D3-U112.pdf>
See store item page for other formats.