


RW17-1D3-U017 Cut Sheet

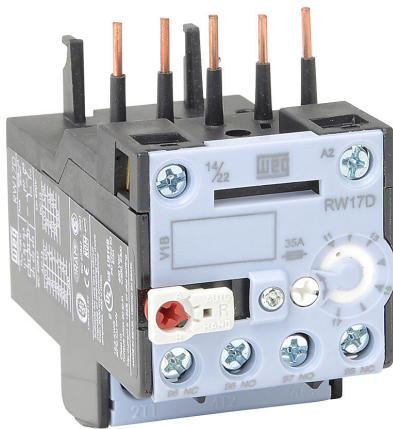

WEG Electric RW17-1D series thermal overload relay, 11.0-17.0A adjustable, bi-metallic, direct mount power connection(s). For use with CWC07 through CWC016 series miniature contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW17-1D3-U017>

Technical Specifications

| | |
|--------------------------|--|
| Brand | WEG Electric |
| Item | Relay |
| Series | RW17-1D |
| Relay Type | Thermal overload |
| Full Load Amperage Range | 11.0-17.0A adjustable |
| Operation Type | Bi-metallic |
| Auxiliary Contacts | (1) N.O. / (1) N.C. |
| Trip Class | Trip Class 10 |
| Phase Loss Sensitive | Yes |
| Connection | Direct mount power |
| For Use With | CWC07 through CWC016 series miniature contactors |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | E189202 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |