


RW27-2D3-D028 Cut Sheet

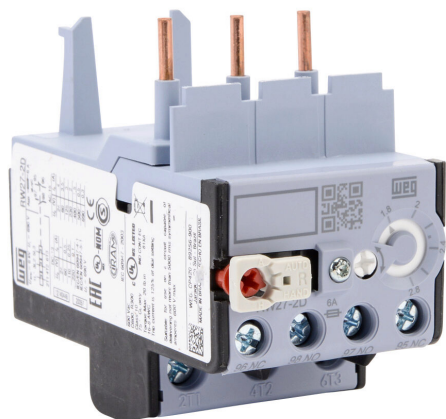

WEG Electric RW27-2D series thermal overload relay, 1.8-2.8A adjustable, bi-metallic, direct mount power connection(s). For use with CWB9 to CWB38 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW27-2D3-D028>

Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RW27-2D
Relay Type	Thermal overload
Full Load Amperage Range	1.8-2.8A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O./ (1) N.C.
Trip Class	Trip Class 10
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB9 to CWB38 series contactors

Agency Approvals

UL Listed File #	E189202
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document