


RW27-2D3-D028 Cut Sheet

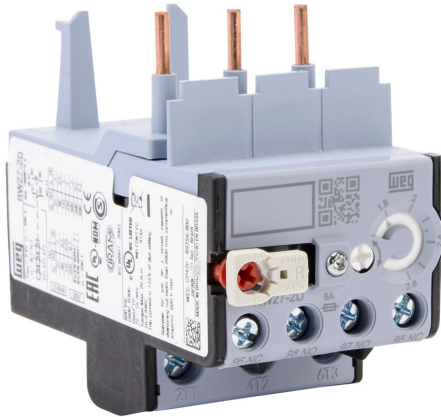

WEG Electric RW27-2D series thermal overload relay, 1.8-2.8A adjustable, bi-metallic, direct mount power connection(s). For use with CWB9 to CWB38 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW27-2D3-D028>

Technical Specifications

| | |
|---------------------------------|---------------------------------|
| Brand | WEG Electric |
| Item | Relay |
| Series | RW27-2D |
| Relay Type | Thermal overload |
| Full Load Amperage Range | 1.8-2.8A adjustable |
| Operation Type | Bi-metallic |
| Auxiliary Contacts | (1) N.O./ (1) N.C. |
| Trip Class | Trip Class 10 |
| Phase Loss Sensitive | Yes |
| Ground Fault Protection | No |
| Connection | Direct mount power |
| For Use With | CWB9 to CWB38 series contactors |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E189202 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/RW27-2D3-D028.pdf>
See store item page for other formats.