


RW27-2D3-D125 Cut Sheet

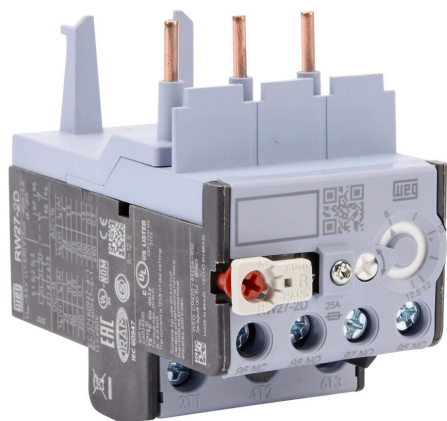

WEG Electric RW27-2D series thermal overload relay, 8.0-12.5A Adjustable, bi-metallic, direct mount power connection(s). For use with CWB9 to CWB38 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW27-2D3-D125>

Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RW27-2D
Relay Type	Thermal overload
Full Load Amperage Range	8.0-12.5A Adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB9 to CWB38 series contactors

Agency Approvals

UL Listed File #	E189202
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/RW27-2D3-D125.pdf>
See store item page for other formats.