


# RW27-2D3-U017 Cut Sheet

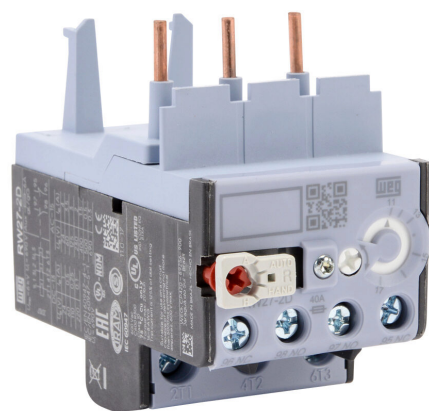

WEG Electric RW27-2D series thermal overload relay, 11.0-17.0A adjustable, bi-metallic, direct mount power connection(s). For use with CWB9 to CWB38 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW27-2D3-U017>

## Technical Specifications

|                          |                                 |
|--------------------------|---------------------------------|
| Brand                    | WEG Electric                    |
| Item                     | Relay                           |
| Series                   | RW27-2D                         |
| Relay Type               | Thermal overload                |
| Full Load Amperage Range | 11.0-17.0A adjustable           |
| Operation Type           | Bi-metallic                     |
| Auxiliary Contacts       | (1) N.O. / (1) N.C.             |
| Trip Class               | Trip Class 10                   |
| Phase Loss Sensitive     | Yes                             |
| Ground Fault Protection  | No                              |
| Connection               | Direct mount power              |
| For Use With             | CWB9 to CWB38 series contactors |

## Agency Approvals

|                      |  |
|----------------------|--|
| UL Listed File #     | E189202                                |
| UL Recognized File # | None                                   |
| UL Hazardous File #  | None                                   |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | None                                   |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |