


# RW67-5D3-U070 Cut Sheet

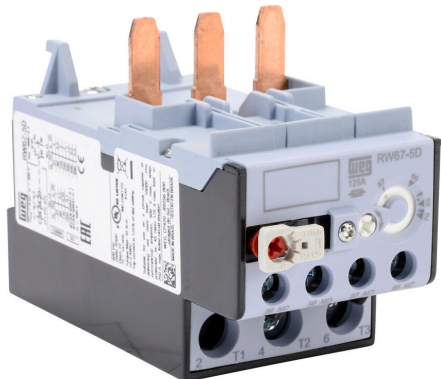

WEG Electric RW67-5D series thermal overload relay, 57.0-70.0A adjustable, bi-metallic, direct mount power connection(s). For use with CWB40 to CWB80 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RW67-5D3-U070>

## Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RW67-5D
Relay Type	Thermal overload
Full Load Amperage Range	57.0-70.0A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB40 to CWB80 series contactors

## Agency Approvals

UL Listed File #	E189202
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/RW67-5D3-U070.pdf>  
See store item page for other formats.