


# RWB40E-3-A4U040 Cut Sheet

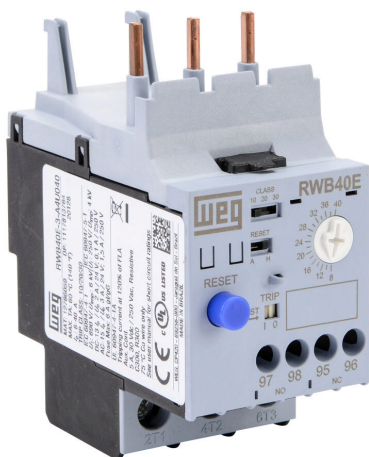

WEG Electric RWB40E series electronic overload relay, 8.0-40.0A adjustable, solid state, direct mount power connection(s). For use with CWB9 to CWB38 series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RWB40E-3-A4U040>

## Technical Specifications

Brand	WEG Electric
Item	Relay
Series	RWB40E
Relay Type	Electronic overload
Full Load Amperage Range	8.0-40.0A adjustable
Operation Type	Solid state
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Selectable 10/20/30
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	CWB9 to CWB38 series contactors
Additional Information	Self powered

## Agency Approvals

UL Listed File #	E172121
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/RWB40E-3-A4U040.pdf>  
See store item page for other formats.