


# RWB40E-3-R4U040 Cut Sheet

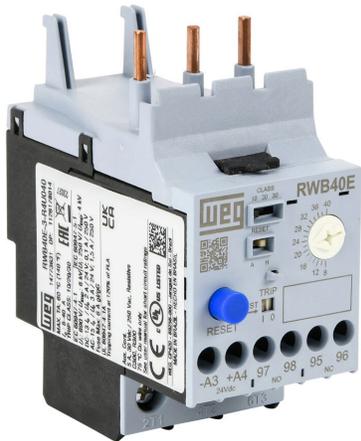

WEG Electric RWB40E series electronic overload relay, 8–40.0A adjustable, solid state, remote/local reset, direct mount power connection(s). For use with CWB9 to CWB38 and CWBN00 to CWBN1series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RWB40E-3-R4U040>

## Technical Specifications

<b>Brand</b>	WEG Electric
<b>Item</b>	Relay
<b>Series</b>	RWB40E
<b>Relay Type</b>	Electronic overload
<b>Full Load Amperage Range</b>	8–40.0A adjustable
<b>Operation Type</b>	Solid state
<b>Auxiliary Contacts</b>	(1) N.O./(1) N.C.
<b>Trip Class</b>	Trip Class 10/20/30

<b>Reset</b>	Remote/local
<b>Phase Loss Sensitive</b>	Yes
<b>Ground Fault Protection</b>	No
<b>Connection</b>	Direct mount power
<b>For Use With</b>	CWB9 to CWB38 and CWBN00 to CWBN1series contactors
<b>Additional Information</b>	Self powered

## Agency Approvals

<b>UL Listed File #</b>	E189202
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/RWB40E-3-R4U040.pdf>  
See store item page for other formats.