


S6648AT Cut Sheet

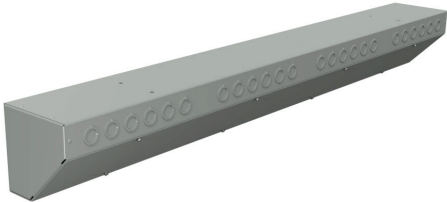

Wiegmann wiring trough, 6 x 6 x 48in (HxDxL), NEMA 1, corner mount, with knockouts, carbon steel, ANSI 61 gray, powder coat finish, screw cover.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/S6648AT>

Technical Specifications

Brand	Wiegmann
Item	Wiring trough
NEMA Rating	1
Nominal Enclosure Dimensions	6 x 48 x 6in (HxWxD)
Enclosure Height	6.00in
Enclosure Depth	6.00in
Enclosure Length	48.00in

Mounting	Corner
Integral Mounting Feet	No
Knockouts	Yes
Material	Carbon steel
Color	ANSI 61 gray
Finish	Powder coat
Cover Type	Screw cover

Agency Approvals

UL Listed File #	E32576
UL Recognized File #	N/A
UL Hazardous File #	N/A
CE	None
CSA File #	N/A
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/S6648AT.pdf>
See store item page for other formats.