


# S8824AT Cut Sheet

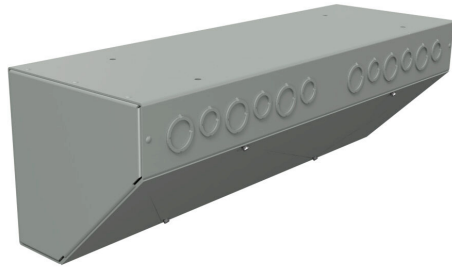

Wiegmann wiring trough, 8 x 8 x 24in (HxDxL), NEMA 1, corner mount, with knockouts, carbon steel, ANSI 61 gray, powder coat finish, screw cover.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/S8824AT>

## Technical Specifications

<b>Brand</b>	Wiegmann
<b>Item</b>	Wiring trough
<b>NEMA Rating</b>	1
<b>Nominal Enclosure Dimensions</b>	8 x 24 x 8in (HxWxD)
<b>Enclosure Height</b>	8.00in
<b>Enclosure Depth</b>	8.00in
<b>Enclosure Length</b>	24.00in

<b>Mounting</b>	Corner
<b>Integral Mounting Feet</b>	No
<b>Knockouts</b>	Yes
<b>Material</b>	Carbon steel
<b>Color</b>	ANSI 61 gray
<b>Finish</b>	Powder coat
<b>Cover Type</b>	Screw cover

## Agency Approvals

<b>UL Listed File #</b>	E32576
<b>UL Recognized File #</b>	N/A
<b>UL Hazardous File #</b>	N/A
<b>CE</b>	None
<b>CSA File #</b>	N/A
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/S8824AT.pdf>  
See store item page for other formats.