


SAC-16-4U-1YL-1 Cut Sheet

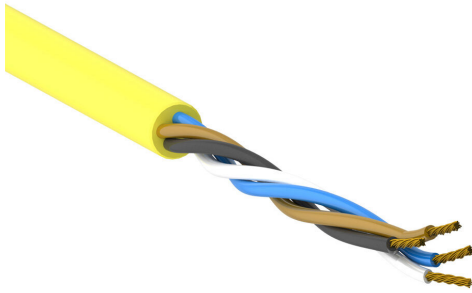

AutomationDirect flexible sensor/actuator cable, unshielded, 4 conductors, 16 AWG, bare copper, PVC conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-16-4U-1YL-1>

Technical Specifications

Brand	AutomationDirect	Conductor Insulation Color	Black, brown, blue and white
Item	Cable	Shielding	Unshielded
Wire/Cable Type	Sensor/actuator	Jacket Material	PVC
UL Wire/Cable Type	AWM	Jacket Color	Yellow
Applicable Standards	UL 2464	Nominal Overall Cable Diameter	0.26 in
Application	Sensor/actuator	Bulk Length	Cut to length
Flexibility	Flexible	Package Type	• 30–99 ft = Coil
Voltage Rating	300 V		• 100–575 ft = 14 x 7 in Reel
Conductors	4 conductors		• 576–825 ft = 14 x 10 in Reel
Conductor Size	16 AWG		• 826–1265 ft = 16 x 10 in Reel
Conductor Stranding	26-stranded		• 1266–1765 ft = 18 x 10 in Reel
Conductor Material	Bare copper		• 1766–2295 ft = 18 x 13 in Reel
Conductor Insulation Material	PVC		• 2296–5000 ft = 24 x 17 in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document