


SAC-16-4U-2YL-1 Cut Sheet

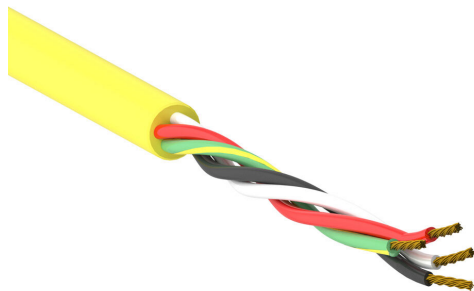

AutomationDirect flexible sensor/actuator cable, unshielded, 4 conductors, 16 AWG, bare copper, PVC conductor insulation material, black, white, red and green/yellow, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-16-4U-2YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300 V
Conductors	4 conductors
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, white, red and green/yellow
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.26 in
Bulk Length	Cut to length
Package Type	• 30–99 ft = Coil • 100–575 ft = 14 x 7 in Reel • 576–825 ft = 14 x 10 in Reel • 826–1265 ft = 16 x 10 in Reel • 1266–1765 ft = 18 x 10 in Reel • 1766–2295 ft = 18 x 13 in Reel • 2296–5000 ft = 24 x 17 in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document