


SAC-16-5U-1YL-1 Cut Sheet

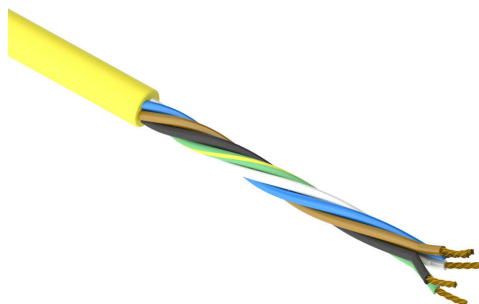

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 16 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-16-5U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300 V
Conductors	5 conductors
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, blue, white and green/yellow

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.283 in
Bulk Length	Cut to length
Package Type	• 30–99 ft = Coil • 100–485 ft = 14 x 7 in Reel • 486–695 ft = 14 x 10 in Reel • 696–1065 ft = 16 x 10 in Reel • 1066–1490 ft = 18 x 10 in Reel • 1491–1940 ft = 18 x 13 in Reel • 1941–4335 ft = 24 x 17 in Wooden Reel • 4336–5000 ft = 30 x 17 in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document