


SAC-20-4U-1YL-1 Cut Sheet

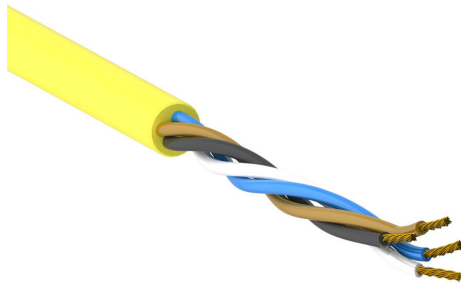

AutomationDirect flexible sensor/actuator cable, unshielded, 4 conductors, 20 AWG, bare copper, PVC conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-20-4U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300 V
Conductors	4 conductors
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, blue and white
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.204 in
Bulk Length	Cut to length
Package Type	• 30–99 ft = Coil • 100–935 ft = 14 x 7 in Reel • 936–1340 ft = 14 x 10 in Reel • 1341–2055 ft = 16 x 10 in Reel • 2056–2870 ft = 18 x 10 in Reel • 2871–3730 ft = 18 x 13 in Reel • 3731–5000 ft = 24 x 17 in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document