


SAC-20-5U-1YL-1 Cut Sheet

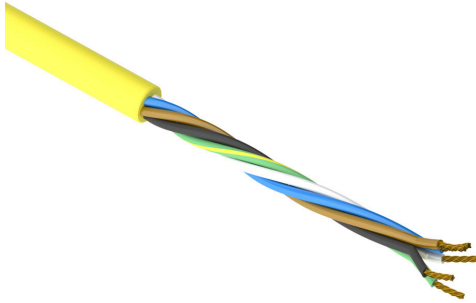

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 20 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-20-5U-1YL-1>

Technical Specifications

Brand	AutomationDirect	Conductor Insulation Color	Black, brown, blue, white and green/yellow
Item	Cable	Shielding	Unshielded
Wire/Cable Type	Sensor/actuator	Jacket Material	PVC
UL Wire/Cable Type	AWM	Jacket Color	Yellow
Applicable Standards	UL 2464	Nominal Overall Cable Diameter	0.22 in
Application	Sensor/actuator	Bulk Length	Cut to length
Flexibility	Flexible	Package Type	• 30–99 ft = Coil
Voltage Rating	300 V		• 100–805 ft = 14 x 7 in Reel
Conductors	5 conductors		• 806–1150 ft = 14 x 10 in Reel
Conductor Size	20 AWG		• 1151–1765 ft = 16 x 10 in Reel
Conductor Stranding	10-stranded		• 1766–2465 ft = 18 x 10 in Reel
Conductor Material	Bare copper		• 2466–3205 ft = 18 x 13 in Reel
Conductor Insulation Material	PVC		• 3206–5000 ft = 24 x 17 in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document