


# SAC-22-3U-1YL-1 Cut Sheet

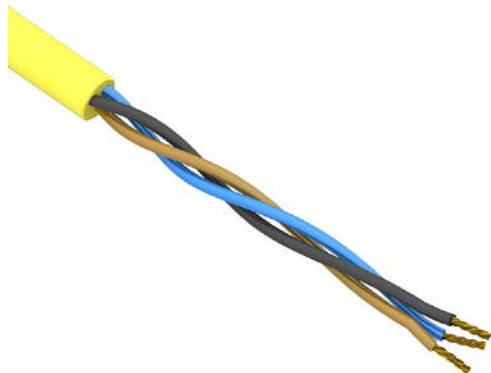

AutomationDirect flexible sensor/actuator cable, unshielded, 3 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown and blue, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-3U-1YL-1>

## Technical Specifications

<b>Brand</b>	AutomationDirect
<b>Item</b>	Cable
<b>Wire/Cable Type</b>	Sensor/actuator
<b>UL Wire/Cable Type</b>	AWM
<b>Applicable Standards</b>	UL 2464
<b>Application</b>	Sensor/actuator
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	3 conductors
<b>Conductor Size</b>	22 AWG
<b>Conductor Stranding</b>	19-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	PVC
<b>Conductor Insulation Color</b>	Black, brown and blue
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Yellow
<b>Nominal Overall Cable Diameter</b>	0.177in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 99ft = Coil</li><li>• 100 to 900ft = 14 x 7in Reel</li><li>• 901 to 1425ft = 14 x 10in Reel</li><li>• 1426 to 2300ft = 16 x 10in Reel</li><li>• 2301 to 3350ft = 18 x 10in Reel</li><li>• 3351 to 4200ft = 18 x 13in Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E505482
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	LL274638
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	None