


# SAC-22-3U-1YL-1 Cut Sheet

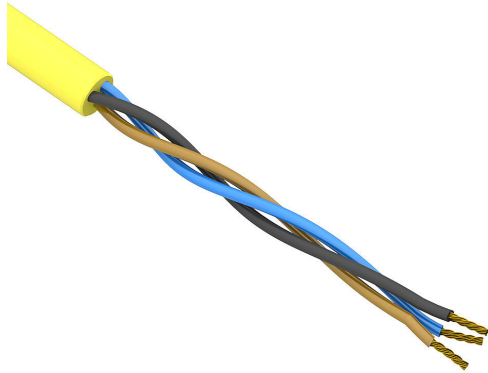

AutomationDirect flexible sensor/actuator cable, unshielded, 3 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown and blue, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-3U-1YL-1>

## Technical Specifications

<b>Brand</b>	AutomationDirect	<b>Conductor Insulation Color</b>	Black, brown and blue
<b>Item</b>	Cable	<b>Shielding</b>	Unshielded
<b>Wire/Cable Type</b>	Sensor/actuator	<b>Jacket Material</b>	PVC
<b>UL Wire/Cable Type</b>	AWM	<b>Jacket Color</b>	Yellow
<b>Applicable Standards</b>	UL 2464	<b>Nominal Overall Cable Diameter</b>	0.177in
<b>Application</b>	Sensor/actuator	<b>Bulk Length</b>	Cut to length
<b>Flexibility</b>	Flexible	<b>Package Type</b>	<ul style="list-style-type: none"><li>• 30 to 99ft = Coil</li><li>• 100 to 1245ft = 14 x 7in Reel</li><li>• 1246 to 1780ft = 14 x 10in Reel</li><li>• 1781 to 2725ft = 16 x 10in Reel</li><li>• 2726 to 3810ft = 18 x 10in Reel</li><li>• 3811 to 4955ft = 18 x 13in Reel</li><li>• 4956 to 5000ft = 24 x 17in Wooden Reel</li></ul>
<b>Voltage Rating</b>	300V		
<b>Conductors</b>	3 conductors		
<b>Conductor Size</b>	22 AWG		
<b>Conductor Stranding</b>	19-stranded		
<b>Conductor Material</b>	Bare copper		
<b>Conductor Insulation Material</b>	PVC		

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E505482
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	LL274638
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>