


SAC-22-4U-1YL-1 Cut Sheet

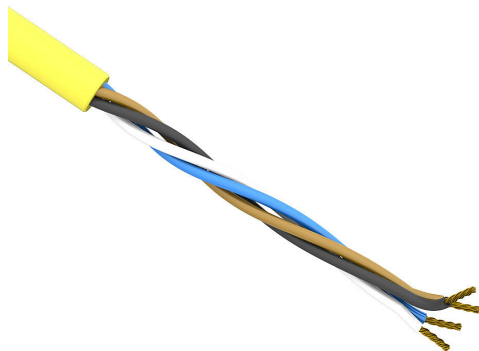

AutomationDirect flexible sensor/actuator cable, unshielded, 4 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-4U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300V
Conductors	4 conductors
Conductor Size	22 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, blue and white
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.19in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 30 to 99ft = Coil• 100 to 1080ft = 14 x 7in Reel• 1081 to 1545ft = 14 x 10in Reel• 1546 to 2365ft = 16 x 10in Reel• 2366 to 3305ft = 18 x 10in Reel• 3306 to 4300ft = 18 x 13in Reel• 4301 to 5000ft = 24 x 17in Wooden Reel

Agency Approvals

UL Recognized File #	E505482
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document