


# SAC-22-5U-1GY-1 Cut Sheet

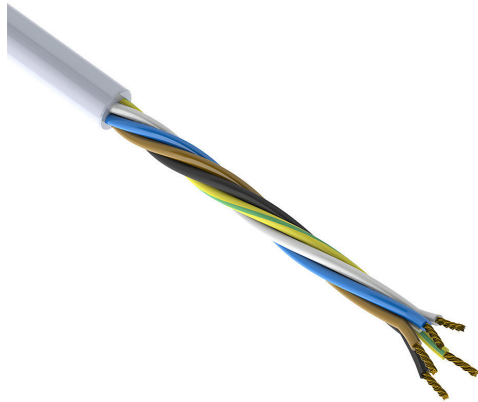

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-5U-1GY-1>

## Technical Specifications

<b>Brand</b>	AutomationDirect	<b>Conductor Insulation Color</b>	Black, brown, blue, white and green/yellow
<b>Item</b>	Cable	<b>Shielding</b>	Unshielded
<b>Wire/Cable Type</b>	Sensor/actuator	<b>Jacket Material</b>	PVC
<b>UL Wire/Cable Type</b>	AWM	<b>Jacket Color</b>	Gray
<b>Applicable Standards</b>	UL 2464	<b>Nominal Overall Cable Diameter</b>	0.204in
<b>Application</b>	Sensor/actuator	<b>Bulk Length</b>	Cut to length
<b>Flexibility</b>	Flexible	<b>Package Type</b>	20 to 99ft = Coil, 100 to 725ft = 14 x 7in Reel, 726 to 1000ft = 14 x 10in Reel, 1001 to 1750ft = 16 x 10in Reel, 1751 to 2500ft = 18 x 10in Reel, 2501 to 3150ft = 18 x 13in Reel, 3052 to 3966ft = 24 x 17in Wooden Reel
<b>Voltage Rating</b>	300V		
<b>Conductors</b>	5 conductors		
<b>Conductor Size</b>	22 AWG		
<b>Conductor Stranding</b>	19-stranded		
<b>Conductor Material</b>	Bare copper		
<b>Conductor Insulation Material</b>	PVC		

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E505482
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	LL274638
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>