


SAC-22-5U-1GY-1 Cut Sheet

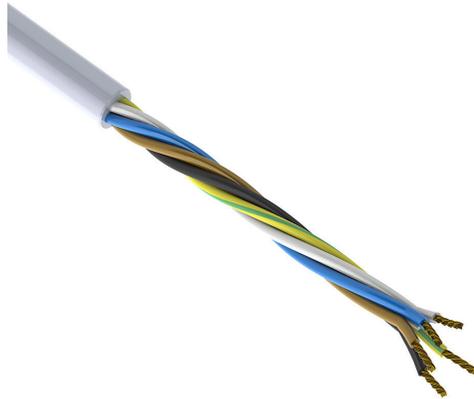

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-5U-1GY-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300V
Conductors	5 conductors
Conductor Size	22 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, blue, white and green/yellow
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.204in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 30 to 99ft = Coil• 100 to 935ft = 14 x 7in Reel• 936 to 1340ft = 14 x 10in Reel• 1341 to 2055ft = 16 x 10in Reel• 2056 to 2870ft = 18 x 10in Reel• 2871 to 3730ft = 18 x 13in Reel• 3731 to 5000ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document