


SAC-22-5U-1YL-1 Cut Sheet

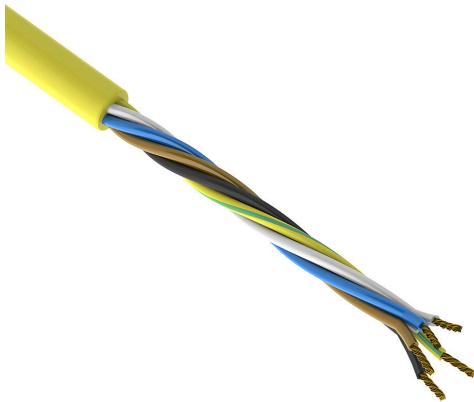

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-5U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300V
Conductors	5 conductors
Conductor Size	22 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, blue, white and green/yellow
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.204in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 725ft = 14 x 7in Reel• 726 to 1000ft = 14 x 10in Reel• 1001 to 1750ft = 16 x 10in Reel• 1751 to 2500ft = 18 x 10in Reel• 2501 to 3150ft = 18 x 13in Reel• 3052 to 3966ft = 24 x 17in Wooden Reel

Agency Approvals

UL Recognized File #	E505482
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document