


# SAC-22-5U-1YL-1 Cut Sheet

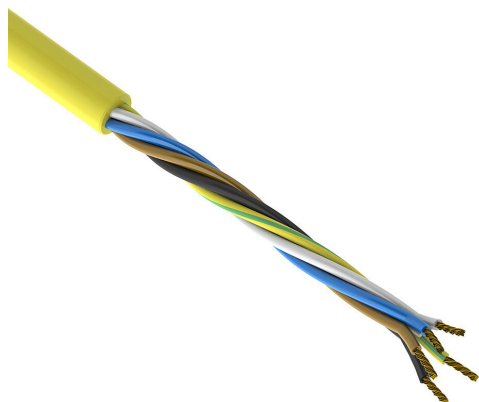

AutomationDirect flexible sensor/actuator cable, unshielded, 5 conductors, 22 AWG, bare copper, PVC conductor insulation material, black, brown, blue, white and green/yellow, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-22-5U-1YL-1>

## Technical Specifications

<b>Brand</b>	AutomationDirect
<b>Item</b>	Cable
<b>Wire/Cable Type</b>	Sensor/actuator
<b>UL Wire/Cable Type</b>	AWM
<b>Applicable Standards</b>	UL 2464
<b>Application</b>	Sensor/actuator
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	5 conductors
<b>Conductor Size</b>	22 AWG
<b>Conductor Stranding</b>	19-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	PVC

<b>Conductor Insulation Color</b>	Black, brown, blue, white and green/yellow
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Yellow
<b>Nominal Overall Cable Diameter</b>	0.204in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 30 to 99ft = Coil</li><li>• 100 to 935ft = 14 x 7in Reel</li><li>• 936 to 1340ft = 14 x 10in Reel</li><li>• 1341 to 2055ft = 16 x 10in Reel</li><li>• 2056 to 2870ft = 18 x 10in Reel</li><li>• 2871 to 3730ft = 18 x 13in Reel</li><li>• 3731 to 5000ft = 24 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Recognized File #</b>	E505482
<b>CSA File #</b>	LL274638
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>