


SAC-24-3U-1YL-1 Cut Sheet

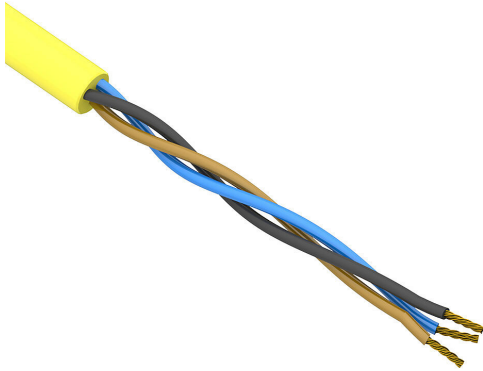

AutomationDirect flexible sensor/actuator cable, unshielded, 3 conductors, 24 AWG, bare copper, PVC conductor insulation material, black, brown and blue, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-24-3U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300V
Conductors	3 conductors
Conductor Size	24 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown and blue
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.167in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 30 to 99ft = Coil• 100 to 1400ft = 14 x 7in Reel• 1401 to 1995ft = 14 x 10in Reel• 1996 to 3065ft = 16 x 10in Reel• 3066 to 4280ft = 18 x 10in Reel• 4281 to 5000ft = 18 x 13in Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document