


SAC-24-4U-1YL-1 Cut Sheet

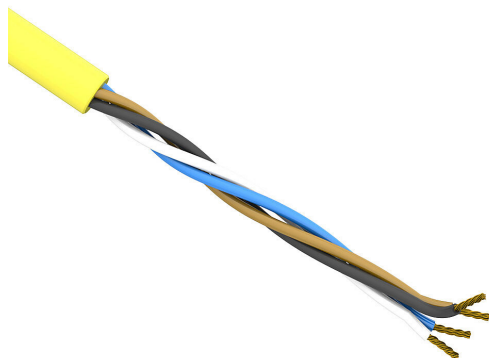

AutomationDirect flexible sensor/actuator cable, unshielded, 4 conductors, 24 AWG, bare copper, PVC conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAC-24-4U-1YL-1>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Wire/Cable Type	Sensor/actuator
UL Wire/Cable Type	AWM
Applicable Standards	UL 2464
Application	Sensor/actuator
Flexibility	Flexible
Voltage Rating	300V
Conductors	4 conductors
Conductor Size	24 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, blue and white
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.178in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 30 to 99ft = Coil• 100 to 1230ft = 14 x 7in Reel• 1231 to 1760ft = 14 x 10in Reel• 1761 to 2695ft = 16 x 10in Reel• 2696 to 3770ft = 18 x 10in Reel• 3771 to 4900ft = 18 x 13in Reel• 4901 to 5000ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E505482
UL Hazardous File #	None
CSA File #	LL274638
RoHS Status	No
EU REACH	View EU REACH document