


# SAU-70-1 Cut Sheet

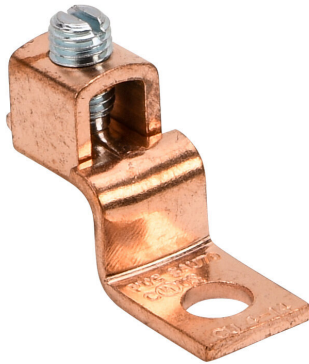

Penn-Union mechanical lug, offset tongue, copper-electrolytic, 70A, 1 openings, (1) 14 AWG solid-4 AWG stranded copper.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SAU-70-1>

## Technical Specifications

<b>Brand</b>	Penn-Union
<b>Item</b>	Mechanical lug
<b>Lug Type</b>	Offset tongue
<b>Material</b>	Copper-electrolytic
<b>Amperage Rating</b>	70A
<b>Number Of Openings</b>	1
<b>Tightening Torque</b>	14-10 AWG 20 in-lb copper, 8 AWG 25 in-lb copper and 6-4 AWG 35 in-lb copper
<b>Conductor Bolt Style</b>	Slotted set screw
<b>Conductor Material</b>	Copper
<b>Conductor Size</b>	(1) 14 AWG solid-4 AWG stranded copper
<b>Mounting Holes</b>	1 hole
<b>Mounting Bolt Size</b>	1/4in

## Agency Approvals

<b>UL Listed File #</b>	E12822, E73393
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/SAU-70-1.pdf>  
See store item page for other formats.