


SC10-LS24-5 Cut Sheet

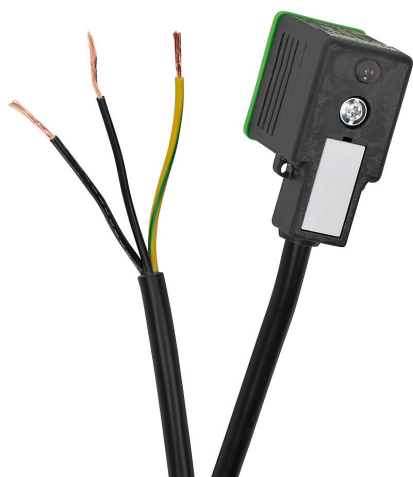

Murrelektronik solenoid valve cable, 10mm DIN 43650 Form B molded connector to 3-wire pigtail, 24 VAC/VDC, 18 AWG, PVC jacket, 16.4ft/5m cable length, surge protection, LED indication.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SC10-LS24-5>

Technical Specifications

Brand	Murrelektronik
Item	Cable
Cable Type	Solenoid valve
Connection 1	10mm DIN 43650 Form B molded connector
Connection 2	3-wire pigtail
Voltage Rating	24 VAC/VDC
Conductor Size	18 AWG
Jacket Material	PVC jacket
Cable Length	16.4ft/5m
Protection Type(s)	surge
Indicating Type	LED indication

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	080128_0_000
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SC10-LS24-5.pdf>
See store item page for other formats.