


SCE-16H1606LP Cut Sheet

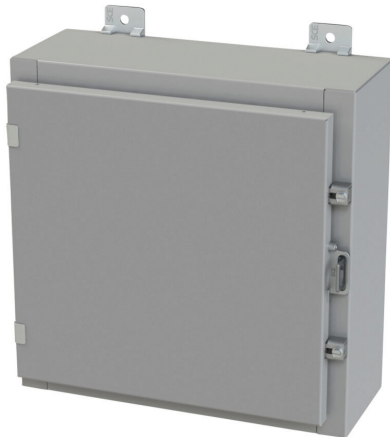

Saginaw enclosure, NEMA 3R/4/12/13, 16 x 16 x 6in (HxWxD), wall mount, carbon steel, ANSI 61 gray, powder coat finish, single-door, plated steel clamps, padlock hasp and staple.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-16H1606LP>

Technical Specifications

| | | | |
|-------------------------------------|------------------------------|----------------------------------|-------------------------|
| Brand | Saginaw | Dual Access | No |
| Item | Enclosure | Knockouts | No |
| Subpanel | Purchase subpanel separately | Bottom Gland Plate | No |
| Slope Top | No | Material | Carbon steel |
| 3-Piece Assembly | No | Color | ANSI 61 gray |
| Vented | No | Finish | Powder coat |
| NEMA Rating | 3R/4/12/13 | Cover Type | Single-door |
| IP Rating | IP66 | Hinge Type | Concealed hinges |
| Nominal Enclosure Dimensions | 16 x 16 x 6in (HxWxD) | Number of Hinges Per Door | 2 |
| Enclosure Height | 16.00in | Latch Type | Plated steel clamps |
| Enclosure Width | 16.00in | Number Of Latches | 2 |
| Enclosure Depth | 7.07in | Padlock Attachment Type | Padlock hasp and staple |
| Mounting | Wall | Shelf | No |
| Integral Mounting Feet | Yes | Padlockable | Yes |
| Integral Mounting Flange | No | Keylocking | No |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E69392 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SCE-16H1606LP.pdf>
See store item page for other formats.