


# SCE-400AFSD Cut Sheet

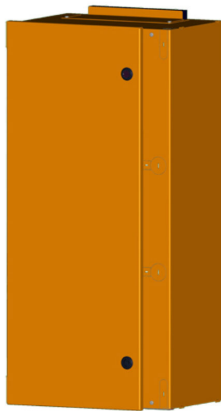

Saginaw add-on disconnect enclosure, NEMA 1, left or right flange, 32 x 15 x 10in (HxWxD), internal mount, carbon steel, orange, powder coat finish, single-door, spring-loaded 1/4-turn.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-400AFSD>

## Technical Specifications

<b>Brand</b>	Saginaw
<b>Item</b>	Add-on disconnect enclosure
<b>Slope Top</b>	No
<b>Vented</b>	No
<b>NEMA Rating</b>	1
<b>IP Rating</b>	IP30
<b>Disconnect Mounting</b>	Left or right flange
<b>Nominal Enclosure Dimensions</b>	32 x 15 x 10in (HxWxD)
<b>Enclosure Height</b>	32.00in
<b>Enclosure Width</b>	15.00in
<b>Enclosure Depth</b>	9.75in
<b>Mounting</b>	Internal

<b>Integral Mounting Feet</b>	No
<b>Material</b>	Carbon steel
<b>Color</b>	Orange
<b>Finish</b>	Powder coat
<b>Cover Type</b>	Single-door
<b>Hinge Type</b>	Continuous hinge
<b>Number of Hinges Per Door</b>	1
<b>Latch Type</b>	Spring-loaded 1/4-turn
<b>Padlockable</b>	No
<b>Keylocking</b>	Yes
<b>Includes</b>	7mm square key

## Agency Approvals

<b>UL Listed File #</b>	E69392
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/SCE-400AFSD.pdf>  
See store item page for other formats.