


SCE-5PBX-RAL1018 Cut Sheet

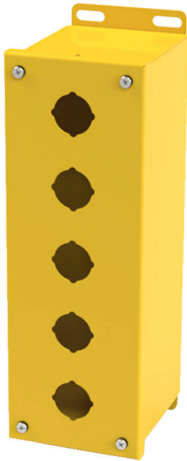

Saginaw pushbutton enclosure, 5 holes, 30mm, NEMA 12/13/4, 12 x 4 x 5in (HxWxD), wall mount, carbon steel, RAL 1018 yellow, powder coat finish, screw cover.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-5PBX-RAL1018>

Technical Specifications

| | |
|-------------------------------------|----------------------|
| Brand | Saginaw |
| Item | Pushbutton enclosure |
| Number of Pushbutton Holes | 5 holes |
| Pushbutton Hole Nominal Size | 30mm |
| Slope Top | No |
| NEMA Rating | 12/13/4 |
| IP Rating | IP66 |
| Nominal Enclosure Dimensions | 12 x 4 x 5in (HxWxD) |
| Enclosure Height | 12.31in |
| Enclosure Width | 4.31in |
| Enclosure Depth | 4.91in |
| Mounting | Wall |
| Integral Mounting Feet | No |
| Integral Mounting Flange | Yes |
| Dual Access | No |
| Knockouts | No |
| Material | Carbon steel |
| Color | RAL 1018 yellow |
| Finish | Powder coat |
| Cover Type | Screw cover |
| Additional Information | Extra deep |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E69392 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |