


SCE-84XD4EW18G Cut Sheet

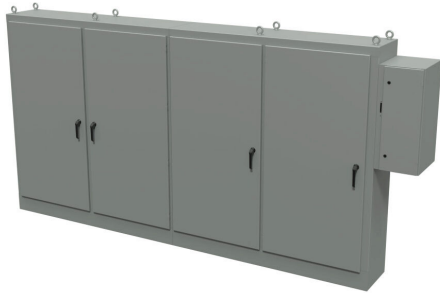

Saginaw enclosure, NEMA 3R/12/13, 84 x 158 x 18in (HxWxD), freestanding, carbon steel, ANSI 61 gray, powder coat finish, 4-door, 3-point padlocking handle, subpanel and external disconnect enclosure included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-84XD4EW18G>

Technical Specifications

Brand	Saginaw	Finish	Powder coat
Item	Enclosure	Cover Type	4-door
Slope Top	No	Hinge Type	Concealed hinges
NEMA Rating	3R/12/13	Number of Hinges Per Door	4
IP Rating	IP55	Latch Type	3-point padlocking handle
Nominal Enclosure Height	84in	Number Of Latches	4
Nominal Enclosure Width	158in	Padlockable	Yes
Nominal Enclosure Depth	18in	Keylocking	No
Mounting	Freestanding	Subpanel	(2) galvanized subpanels included
Dual Access	No	Includes	External disconnect enclosure
Knockouts	No	Additional Information	Purchase operating mechanism, disconnect switch or circuit breaker, and operating handle from disconnect supplier
Material	Carbon steel		
Color	ANSI 61 gray		

Agency Approvals

UL Listed File #	E69392
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SCE-84XD4EW18G.pdf>
See store item page for other formats.