


# SCE-HWK2218 Cut Sheet

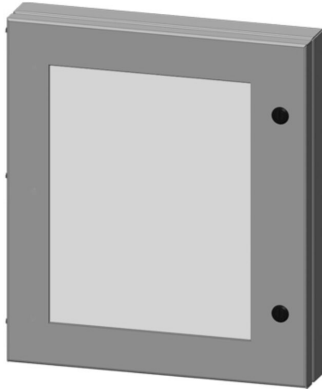

Saginaw universal deep-hinged door, NEMA 3R/12/13, 22.00 x 18.00 x 2.63in, carbon steel, ANSI 61 gray, concealed hinges, polycarbonate window. For use with wall-mount enclosures.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-HWK2218>

## Technical Specifications

<b>Brand</b>	Saginaw
<b>Item</b>	Universal deep-hinged door
<b>NEMA Rating</b>	3R/12/13
<b>Door Size</b>	22.00 x 18.00 x 2.63in
<b>Door Material</b>	Carbon steel
<b>Hinge Type</b>	Concealed hinges
<b>Color</b>	ANSI 61 gray
<b>Finish</b>	Powder coat
<b>Cutout Size</b>	19.50 x 15.50in
<b>Number of Hinges Per Door</b>	3
<b>Latch Type</b>	1/4-turn semi-flush latch
<b>Gasket Type</b>	Oil-resistant neoprene
<b>Window Material</b>	Polycarbonate
<b>Window Size</b>	18.00 x 13.38in
<b>For Use With</b>	Wall-mount enclosures

## Agency Approvals

<b>UL Listed File #</b>	E69392
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>