


# SCE-HWK2822LG Cut Sheet

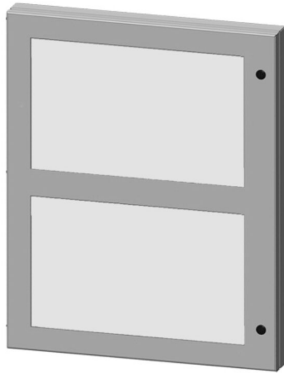

Saginaw universal deep-hinged door, NEMA 3R/12/13, 28.00 x 22.00 x 2.63in, carbon steel, RAL 7035 light gray, concealed hinges, polycarbonate window. For use with wall-mount enclosures.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-HWK2822LG>

## Technical Specifications

<b>Brand</b>	Saginaw
<b>Item</b>	Universal deep-hinged door
<b>NEMA Rating</b>	3R/12/13
<b>Door Size</b>	28.00 x 22.00 x 2.63in
<b>Door Material</b>	Carbon steel
<b>Hinge Type</b>	Concealed hinges
<b>Color</b>	RAL 7035 light gray
<b>Finish</b>	Powder coat

<b>Cutout Size</b>	25.50 x 19.50in
<b>Number of Hinges Per Door</b>	3
<b>Latch Type</b>	1/4-turn semi-flush latch
<b>Gasket Type</b>	Oil-resistant neoprene
<b>Window Material</b>	Polycarbonate
<b>Window Size</b>	(2) 10.88 x 17.38in
<b>For Use With</b>	Wall-mount enclosures

## Agency Approvals

<b>UL Listed File #</b>	E69392
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/SCE-HWK2822LG.pdf>  
See store item page for other formats.