


SCE-L9368ELJW Cut Sheet

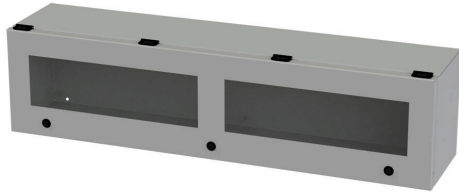

Saginaw wiring trough, 8 x 9 x 36in (HxDxL), NEMA 3R/4/12/13, wall mount, carbon steel, ANSI 61 gray, powder coat finish, single-door, polycarbonate window.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-L9368ELJW>

Technical Specifications

Brand	Saginaw
Item	Wiring trough
Series	EnviroLine Junction
NEMA Rating	3R/4/12/13
IP Rating	IP66
Nominal Enclosure Dimensions	9 x 36 x 8in (HxWxD)
Enclosure Height	9.00in
Enclosure Depth	8.19in
Enclosure Length	36.00in
Mounting	Wall

Integral Mounting Feet	No
Knockouts	No
Material	Carbon steel
Color	ANSI 61 gray
Finish	Powder coat
Cover Type	Single-door
Latch Type	1/4-turn semi-flush latch
Window Material	Polycarbonate
Padlockable	No

Agency Approvals

UL Listed File #	E69392
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SCE-L9368ELJW.pdf>
See store item page for other formats.