


SCE-SKL157280SS Cut Sheet

Saginaw skirt kit, 14.94 x 71.75in, 304 stainless steel, #4 brush finish, vented. For use with 72-80in wide floor-mount enclosures on 15in floor stands.

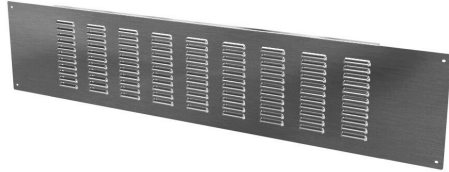

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SCE-SKL157280SS>

Technical Specifications

Brand	Saginaw
Item	Skirt kit
Height	14.94in
Width	71.75in
Material	304 stainless steel
Finish	#4 brush
Vented	Yes
For Use With	72-80in wide floor-mount enclosures on 15in floor stands
Kit Includes	(2) skirt panels and mounting hardware

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SCE-SKL157280SS.pdf>
See store item page for other formats.