


# SE-ANT130 Cut Sheet

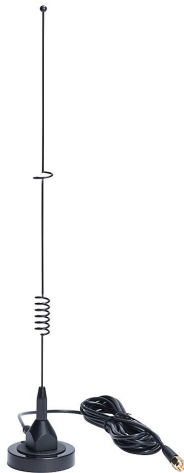

STRIDE whip/straight LTE antenna, magnetic base mount, 9.8ft/3m cable length. For use with SE-SL3011-4G and SE-SL3011-4GG VPN routers.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SE-ANT130>

## Technical Specifications

Brand	STRIDE
Item	LTE antenna
Antenna Type	Whip/straight
Antenna Connector	SMA (M)
Frequency Range	700-960 MHz / 1.71-3.5 GHz
Gain	-2.5dBi / 0.1dBi
Maximum Power	50W
Height	13in
Mounting	Magnetic base
Cable Length	9.8ft/3m
For Use With	SE-SL3011-4G and SE-SL3011-4GG VPN routers
Application	LTE, CDMA, GSM, HSPA, UMTS

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/SE-ANT130.pdf>  
See store item page for other formats.