


# SE-SW8MG-4P Cut Sheet

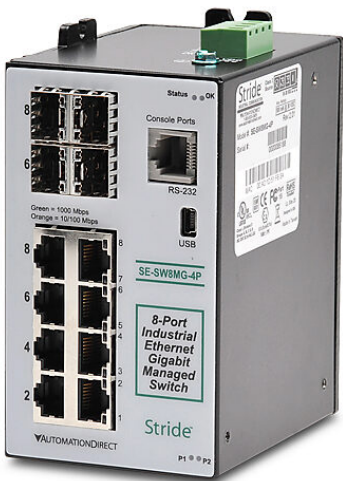

STRIDE industrial managed Ethernet switch, 8 ports, (8) Ethernet Gigabit (RJ45) and (4) SFP combo Gigabit port(s), EtherNet/IP and Modbus TCP, -40 to +75 deg C, metal housing, IP40, 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SE-SW8MG-4P>

## Technical Specifications

Brand	STRIDE
Item	Ethernet switch
Grade	Industrial
Switch Type	Managed
Number of Ports	8
Communication Port and Connection Type(s)	<ul style="list-style-type: none"><li>• (8) Ethernet Gigabit (RJ45)</li><li>• (4) SFP combo Gigabit</li></ul>
Port Protocol(s)	<ul style="list-style-type: none"><li>• Modbus TCP</li><li>• webserver (secure HTTPs)</li></ul>

Port Speed(s)	10/100/1000 Mbps auto-detect
Operating Temperature	-40 to +75 deg C
Housing Material	Metal
IP Rating	IP40
Mounting	35mm DIN rail
Additional Information	Optional SFP modules sold separately
Application	Hazardous location rated

## Agency Approvals

UL Listed File #	E200031
UL Recognized File #	None
UL Hazardous File #	E200031
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/SE-SW8MG-4P.pdf>  
See store item page for other formats.