


SEL.2.202T Cut Sheet

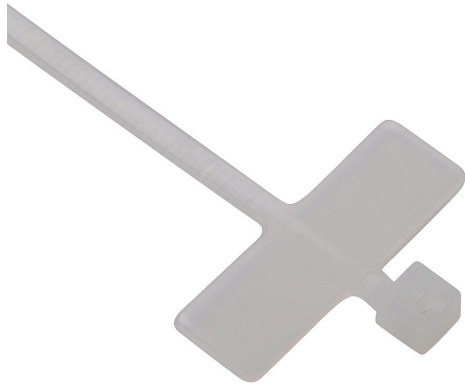

SapiSelco identification cable tie, 3.94in length, 0.1in width, 24.25lb tensile strength, 0.98in maximum bundle diameter, natural, nylon, (1) 0.31 x 0.98in bottom mounted transversal ID tag. Package of 100.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEL.2.202T>

Technical Specifications

Brand	SapiSelco
Item	Cable tie
Cable Tie Type	Identification
Length	3.94in
Width	0.1in
Tensile Strength	24.25lb
Maximum Bundle Diameter	0.98in
Color	Natural
Material	Nylon
Temperature Rating	+5 to +167 deg F
Marker Type	(1) 0.31 x 0.98in bottom mounted transversal ID tag
Quantity per Pack	100

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document