


# SEL.2.223T Cut Sheet

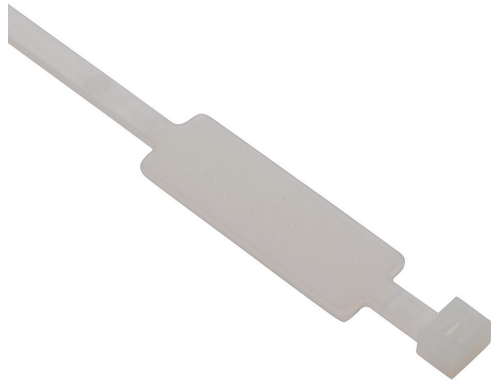

SapiSelco identification cable tie, 7.87in length, 0.19in width, 61.73lb tensile strength, 1.97in maximum bundle diameter, natural, nylon, (1) leg with (1) 1.38 x 0.51in longitudinal ID tag. Package of 100.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEL.2.223T>

## Technical Specifications

<b>Brand</b>	SapiSelco
<b>Item</b>	Cable tie
<b>Cable Tie Type</b>	Identification
<b>Length</b>	7.87in
<b>Width</b>	0.19in
<b>Tensile Strength</b>	61.73lb
<b>Maximum Bundle Diameter</b>	1.97in
<b>Color</b>	Natural
<b>Material</b>	Nylon
<b>Temperature Rating</b>	+5 to +167 deg F
<b>Marker Type</b>	(1) leg with (1) 1.38 x 0.51in longitudinal ID tag
<b>Quantity per Pack</b>	100

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>