


SEL.21.202 Cut Sheet

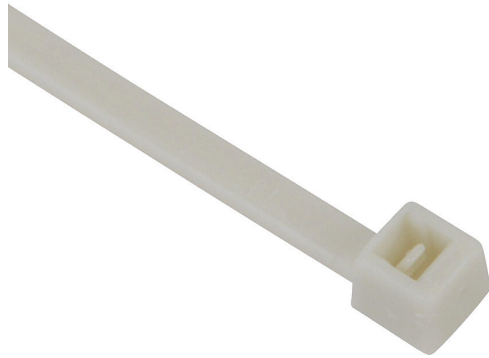

SapiSelco general purpose cable tie, 3.94in length, 0.1in width, 24.25lb tensile strength, 0.94in maximum bundle diameter, gray, nylon. Package of 100.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEL.21.202>

Technical Specifications

Brand	SapiSelco
Item	Cable tie
Cable Tie Type	General purpose
Length	3.94in
Width	0.1in
Tensile Strength	24.25lb
Maximum Bundle Diameter	0.94in
Color	Gray
Material	Nylon
Temperature Rating	-40 to +185 deg F
Quantity per Pack	100

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document