


SEOOW-14-4BK-1 Cut Sheet

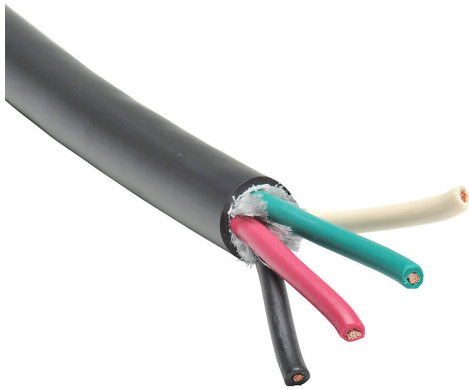

Southwire portable cord, unshielded, SEOOW, 600V, 4 conductors (includes ground), 14 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEOOW-14-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SEOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	4 conductors (includes ground)
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	TPE
Jacket Color	Black
Nominal Overall Cable Diameter	0.575in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 120ft = 14 x 7in Reel• 121 to 170ft = 14 x 10in Reel• 171 to 260ft = 16 x 10in Reel• 261 to 360ft = 18 x 10in Reel• 361 to 470ft = 18 x 13in Reel• 471 to 1050ft = 24 x 17in Wooden Reel• 1051 to 1680ft = 30 x 17in Wooden Reel• 1681 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement