


SEOOW-14-4BK-1 Cut Sheet

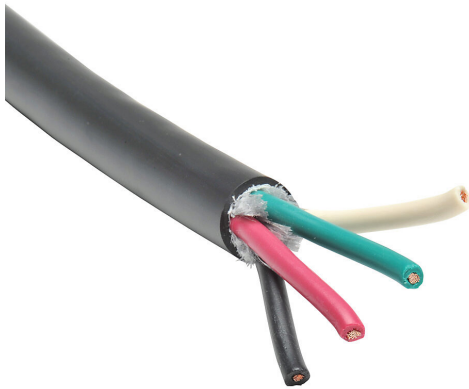

Southwire portable cord, unshielded, SEOOW, 600V, 4 conductors (includes ground), 14 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEOOW-14-4BK-1>

Technical Specifications

Brand	Southwire	Shielding	Unshielded
Item	Cord	Jacket Material	TPE
Wire/Cable Type	Portable	Jacket Color	Black
UL Wire/Cable Type	SEOOW	Nominal Overall Cable Diameter	0.575in
Applicable Standards	UL 62	Bulk Length	Cut to length
Application	General purpose	Package Type	1 to 50ft = Coil, 51 to 110ft = 14 x 7in Reel, 111 to 160ft = 14 x 10in Reel, 161 to 260ft = 16 x 10in Reel, 261 to 360ft = 18 x 10in Reel, 361 to 470ft = 18 x 13in Reel, 471 to 1030ft = 24 x 17in Wooden Reel, 1031 to 1690ft = 30 x 17in Wooden Reel, 1691 to MAX = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	600V		
Conductors	4 conductors (includes ground)		
Conductor Size	14 AWG		
Conductor Stranding	41-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	TPE		
Conductor Insulation Color	Black, white, red and green		

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement