


# SEOOW-16-4BK-1 Cut Sheet

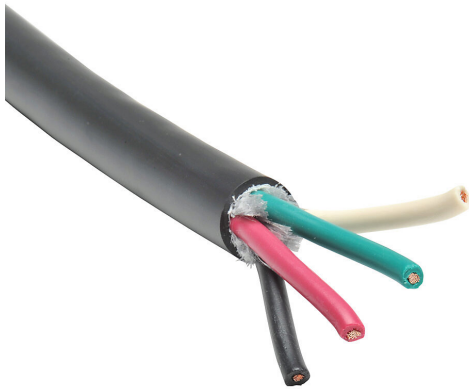

Southwire portable cord, unshielded, SEOOW, 600V, 4 conductors (includes ground), 16 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEOOW-16-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SEOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	16 AWG
<b>Conductor Stranding</b>	26-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	TPE
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	TPE
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.42in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 220ft = 14 x 7in Reel</li><li>• 221 to 315ft = 14 x 10in Reel</li><li>• 316 to 485ft = 16 x 10in Reel</li><li>• 486 to 675ft = 18 x 10in Reel</li><li>• 676 to 880ft = 18 x 13in Reel</li><li>• 881 to 1970ft = 24 x 17in Wooden Reel</li><li>• 1971 to 3150ft = 30 x 17in Wooden Reel</li><li>• 3151 to 5000ft = Large Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>